


19" Blown Tube Patch Shelf

Prysmian Part Number: *XBFSC00295*

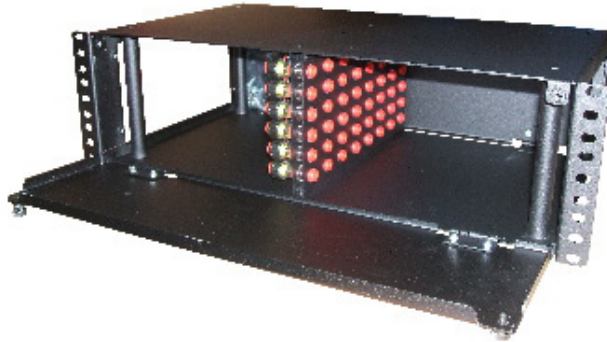

The 19" Blown Tube Patch Shelf provides a solution for connecting up to 48 blown fibre tubes of 5mm in diameter. The shelf is 3U in height and can be mounted into a 19" rack or street-side cabinet. The connectors inside the shelf are gas block connectors which means the shelf is ideal for connecting external tubes to internal tubes. The unit is supplied with the 48 gas block connectors mounted into the steelwork and the fixings required to install it into a rack or street-side cabinet.

Features and Benefits

- Provides suitable management for 5mm blown fibre tubes.
- Up to 48 gas block connectors can be accommodated.
- Compatible with 19" rack practice (3U) for direct mounting.

Kit Contents

- 4 x Fixing Screw
- 4 x Cage nuts
- 48 x Gas Block connectors

Additional Items Required

- 5mm Tube

Technical Data

- Max number of 5mm tubes: 48
- Max Cable size: 24 Way Blown Cable
- Required space envelope (mm): (w) 490 x (d) 260 x (h) 135
- Operating temperature: -20°C to + 60°C (5 to 93% RH)
- Material:-
 - Metalwork: Mild Steel
- Finish:-
 - Metalwork: Painted Black

Logistics

- Packing Dimensions (mm):
 - (w) 620
 - (d) 475
 - (h) 250
- Packed Weight (kg): 7
- Net weight (kg): 6

Prysmian Telecom Cables & Systems UK Ltd, Chickenhall Lane, Bishopstoke, Hants SO50 6YU, UK

Technical Enquiries +44 (0) 2380 608760 Fax Number +44 (0) 2380 608769

© PRYSMIAN 2008. All Rights Reserved.

The information contained within this document must not be copied, reprinted or reproduced in any form, either wholly or in part, without the written consent of Prysmian. The information is believed correct at the time of issue. Prysmian reserves the right to amend this specification without notice. This specification is not contractually valid unless specifically authorised by Prysmian.